

# Captured Washer Hex Socket Head Cap Screws

Available in Box

# Hex Socket Head Cap Screws with Captured Washer


With Captured Spring Washer / Flat Washer, With Captured Spring Washer / Large Washer, Thick Large Washer



RoHS 10

### Captured Spring Washer Type

Type	Part Number	Material
BOX-SCBZ	Screw	EN 1.4301 Equiv.
	Spring Washer	EN 1.4301 Equiv.

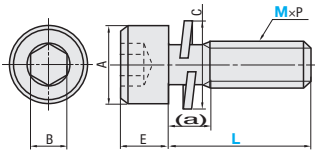

MxP (Coarse)	A	E	B	C	(a)
3x0.5	5.5	3	2.5	5.5	2.4
4x0.7	7	4	3	7	3.5
5x0.8	8.5	5	4	8.5	4.3
6x1.0	10	6	5	11.5	5.1

(a) is the max length (reference) between head surface and the complete thread.


Can be ordered as a separate item. P.178



RoHS 10

### Captured Spring Washer / Flat Washer Type

Type	Part Number	Material
BOX-SCBS	Screw	EN 1.4301 Equiv.
	Spring Washer	EN 1.4301 Equiv.
	Flat Washer	EN 1.4301 Equiv.

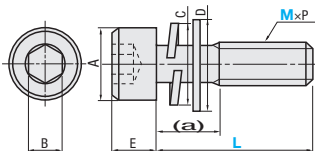

MxP (Coarse)	A	E	B	C	D	(a)
3x0.5	5.5	3	2.5	5.5	7	3
4x0.7	7	4	3	7	9	4.4
5x0.8	8.5	5	4	8.5	10	5.4
6x1.0	10	6	5	11.5	12.5	6.9

(a) is the max length (reference) between head surface and the complete thread.

Can be ordered as a separate item. P.178

Please specify in box quantity when ordering. One box is shipped for an order of 1.

Ordering Example  
Part Number  
BOX-SCBZ5-10  
BOX-SCBS5-10

Box package is cost-saving for in-house stock or when large quantities are needed.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	M-L	Price per pkg.	1 Box	
BOX-SCBZ	3- 6			500 pcs./box
	8			
	10			
	12			
	4- 8			
	10			
	12			
	15			
	20			
	5-10			
	12			
	15			
20				
25				
6-12				200 pcs./box
15				
20				
25				

For orders larger than indicated quantity, please check with WOS.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	M-L	Price per pkg.	1 Box	
BOX-SCBS	3- 6			500 pcs./box
	8			
	10			
	12			
	4- 8			
	10			
	12			
	15			
	20			
	5-10			
	12			
	15			
20				
6-12				200 pcs./box
15				
20				
25				

For orders larger than indicated quantity, please check with WOS.

Hex Socket Head Cap Screws with Captured Washer With Captured Flat Washer / Spring Washer

RoHS 10

CBST SCBS (Stainless Steel)

MxP	A	E	B	C	D	(a)
2x0.4	3.8	2	1.5	3.8	5	2.1
2.5x0.45	4.5	3	2	4.5	6.5	2.7
3x0.5	5.5	3	2.5	5.5	7	3
4x0.7	7	4	3	7	9	4.4
5x0.8	8.5	5	4	8.5	10	5.4
6x1.0	10	6	5	11.5	12.5	6.9
8x1.25	13	8	6	14.5	17	8.4

Part Number	CBST	SCBS	Part Number	CBST	SCBS
Type	M-L	Unit Price	Type	M-L	Unit Price
CBST	2-4		CBST	5-8	
	5			10	
	6			12	
	8			15	
SCBS	2.5-5		SCBS	16	
	6			20	
	8			25	
	10			30	
CBST	3-5		CBST	6-10	
	6			12	
	8			15	
	10			16	
SCBS	6		SCBS	20	
	8			25	
	12			30	
	15			35	
CBST	4-6		CBST	8-15	
	8			16	
	10			20	
	12			25	
SCBS	15		SCBS	30	
	16			35	

Part Number	CBST	SCBS	Part Number	CBST	SCBS
Type	M-L	Unit Price	Type	M-L	Unit Price
SCBS	2-4		CBST	5-8	
	5			10	
	6			12	
	8			15	
SCBS	2.5-5		SCBS	16	
	6			20	
	8			25	
	10			30	
CBST	3-5		CBST	6-10	
	6			12	
	8			15	
	10			16	
SCBS	6		SCBS	20	
	8			25	
	12			30	
	15			35	
CBST	4-6		CBST	8-15	
	8			16	
	10			20	
	12			25	
SCBS	15		SCBS	30	
	16			35	

No specifications available for sizes with no prices shown. For orders larger than indicated quantity, please check with WOS.

Hex Socket Head Cap Screws with Captured Washer Large Washer / Large Thick Washer

RoHS 10

SCBST (Large Washer) SCBSA (Thick Large Washer) Large Washer

Part Number	M	L	MxP	A	E	B	C	D	t	(a)	Unit Price	
Type	mm	Increment					(Max.)	(Max.)	SCBST	SCBSA	SCBST	SCBSA
SCBST	3	10-25	3x0.5	5.5	3	2.5	5.5	10	1	2	4	5
	4		4x0.7	7	4	3	7	12	1	2	4.4	5.4
	5		5x0.8	8.5	5	4	8.5	13	1	2	5.4	6.4
	6		6x1.0	10	6	5	11.5	16	1	2.5	6.9	8.4
SCBSA	8	15-35	8x1.25	13	8	6	14.5	22	1.5	2.5	8.4	9.4

Part Number	M	L	MxP	A	E	B	C	D	t	(a)	Unit Price	
Type	mm	Increment					(Max.)	(Max.)	SCBST	SCBSA	SCBST	SCBSA
SCBST	3	10-25	3x0.5	5.5	3	2.5	5.5	10	1	2	4	5
	4		4x0.7	7	4	3	7	12	1	2	4.4	5.4
	5		5x0.8	8.5	5	4	8.5	13	1	2	5.4	6.4
	6		6x1.0	10	6	5	11.5	16	1	2.5	6.9	8.4
SCBSA	8	15-35	8x1.25	13	8	6	14.5	22	1.5	2.5	8.4	9.4

Ordering Example  
Part Number - L  
SCBST4 - 12

Alterations  
Part Number - L - (NSW)  
SCBST4 - 12 - NSW

Alteration	Code	Spec.
No Spring Washer	NSW	No Spring Washer Only the part ①+③

Hex Socket Head Cap Screws with Captured Washer With Captured Spring Washer

RoHS 10

SCBZ

MxP	A	E	B	C	(a)
3x0.5	5.5	3	2.5	5.5	2.4
4x0.7	7	4	3	7	3.5
5x0.8	8.5	5	4	8.5	4.3
6x1.0	10	6	5	11.5	5.1
8x1.25	13	8	6	14.5	6.2

Part Number	Unit Price	Volume Discount Rate	Part Number	Unit Price	Volume Discount Rate
Type	M-L	1 - 9 pc(s)	Type	M-L	1 - 9 pc(s)
SCBZ	3-6		SCBZ	6-12	
	8			15	
	10			16	
	12			20	
SCBZ	4-8		SCBZ	8-20	
	10			25	
	12			25	
	15			25	
SCBZ	20		SCBZ	5-10	
	15			12	
	16			15	
	20			16	

Part Number	Unit Price	Volume Discount Rate	Part Number	Unit Price	Volume Discount Rate
Type	M-L	1 - 9 pc(s)	Type	M-L	1 - 9 pc(s)
SCBZ	3-6		SCBZ	6-12	
	8			15	
	10			16	
	12			20	
SCBZ	4-8		SCBZ	8-20	
	10			25	
	12			25	
	15			25	
SCBZ	20		SCBZ	5-10	
	15			12	
	16			15	
	20			16	

Ordering Example  
Part Number  
CBST6-20

No specifications available for sizes with no prices shown. For orders larger than indicated quantity, please check with WOS.

Hex Socket Head Cap Screws with Captured Washer Large Washer / Large Thick Washer

RoHS 10

SCBST (Large Washer) SCBSA (Thick Large Washer) Large Washer

Part Number	M	L	MxP	A	E	B	C	D	t	(a)	Unit Price	
Type	mm	Increment					(Max.)	(Max.)	SCBST	SCBSA	SCBST	SCBSA
SCBST	3	10-25	3x0.5	5.5	3	2.5	5.5	10	1	2	4	5
	4		4x0.7	7	4	3	7	12	1	2	4.4	5.4
	5		5x0.8	8.5	5	4	8.5	13	1	2	5.4	6.4
	6		6x1.0	10	6	5	11.5	16	1	2.5	6.9	8.4
SCBSA	8	15-35	8x1.25	13	8	6	14.5	22	1.5	2.5	8.4	9.4

Ordering Example  
Part Number - L  
SCBST4 - 12

Alterations  
Part Number - L - (NSW)  
SCBST4 - 12 - NSW

Alteration	Code	Spec.
No Spring Washer	NSW	No Spring Washer Only the part ①+③